


# Integrated Solution for Delivery Robot/AGV/AMR/無人搬送ロボット

## Interconnect Solutions for Delivery Robot: LiDAR, Camera, Sensor, Wireless and FAN Module Connections

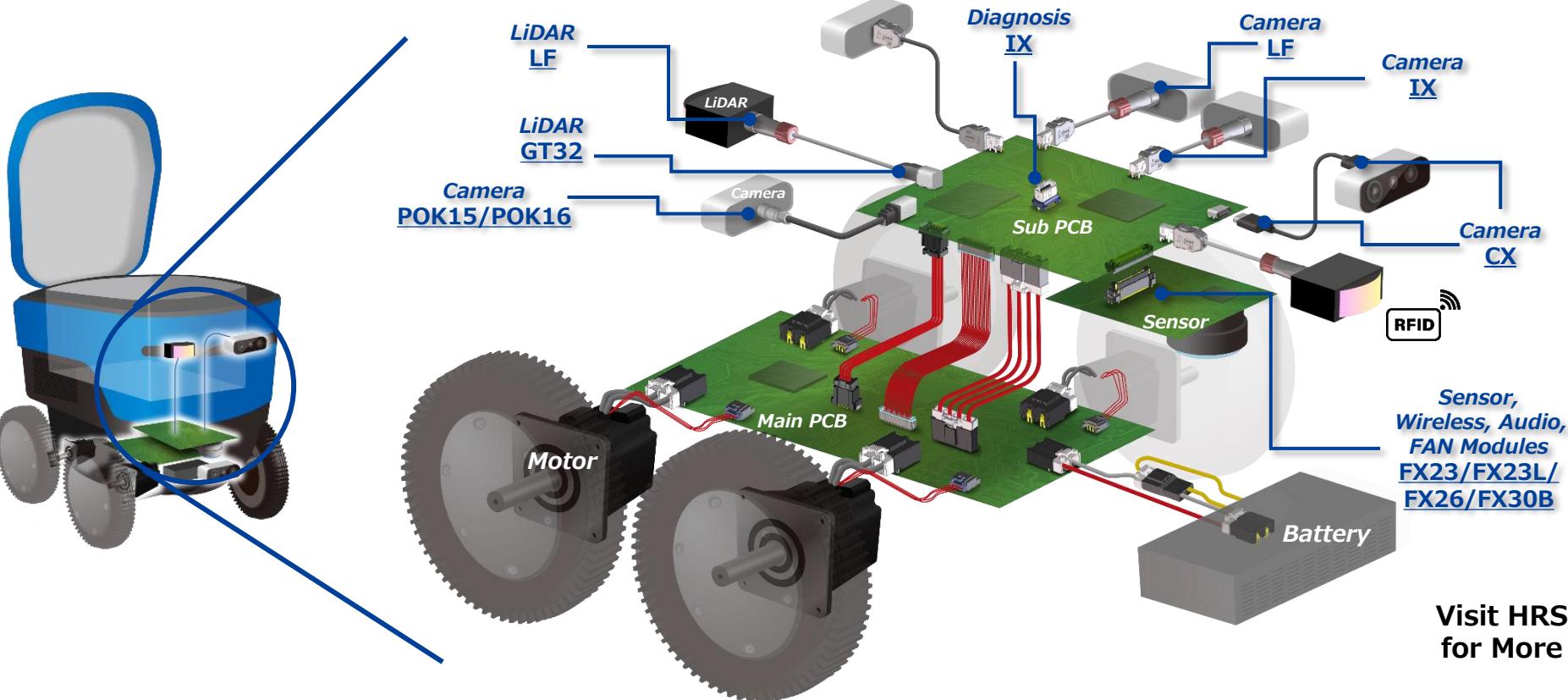

Visit HRS  
for More



### LiDAR & Camera



**IX**  
Compact and Robust Cat.6A I/O



**CX**  
USB Type-C Connector Supporting Up to 20Gbps



**GT32**  
1Gbps, Space-saving Shielded Signal I/O



**POK15/POK16**  
3GHz, Coaxial  
Wire-to-Board &  
Board-to-Board



**LF**  
Shielded  
Waterproof I/O  
Cat.6A

### Sensor, Wireless, and FAN Modules



**FX23/FX23L**  
High Speed Floating  
Board-to-Board with  
Power Contacts




**FX26**  
Vibration Absorbing,  
Floating  
Board-to-Board



**FX30B**  
Board-to-Board  
Power Connectors  
With Misalignment  
Absorption

## Interconnect Solutions for Delivery Robot: Motor Signal, PCB, Motor Power and Battery Connections

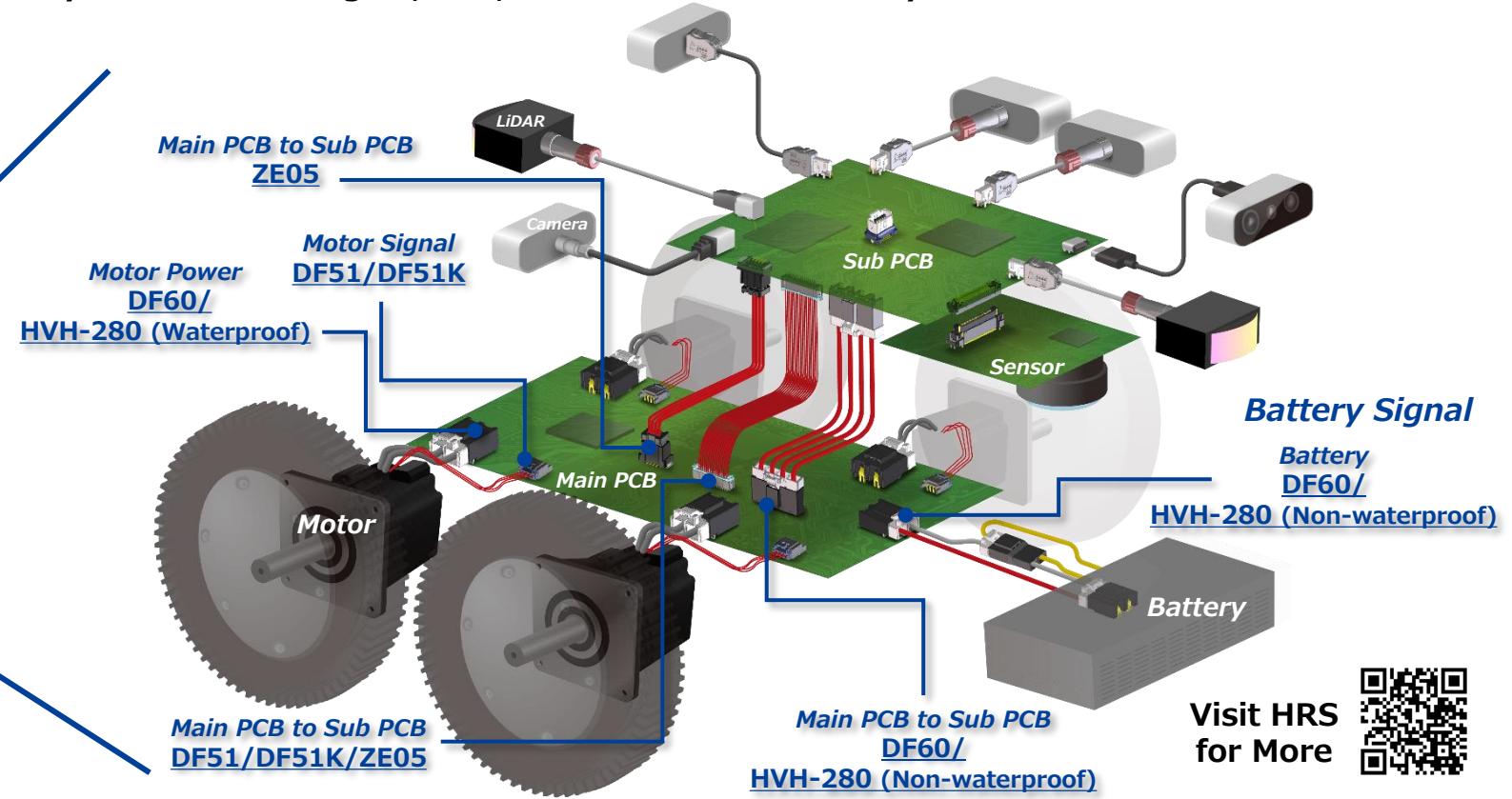

**Visit HRS  
for More**




## **Motor Signal & PCB**



## **ZE05**

125°C Heat-resistant  
High Vibration Resistance

## DF51/DF51K

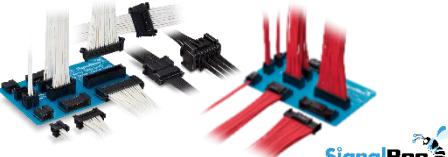

## **Motor Power & Battery**



**HVH-280**  
**(Non-waterproof)**  
125°C Heat-resistant  
Wire-to-Board  
Rated Current: 30A



**HVH-280**  
**(Waterproof)**



**EM30MSD**  
Waterproof  
Finger Protect  
Rated Current: 200A