

External Line Connection



EM30M

1pos. High Current
Circular Connector
IP67 Waterproof
(When Using Cable Ground)
Rated Current:
175A Max. (Waterproof),
200A Max. (Non-waterproof)
Applicable Cable:
42.42-60.57sq



EM40M

1pos. High Current
Circular Connector
IP67 Waterproof
(When Using Cable Ground)
Rated Current:
410A Max. (Waterproof),
450A Max. (Non-waterproof)
Applicable Cable:
117.2-152.05sq

Zero Screw™ Terminal Block



EF2

One Action Positive Lock Design
Rated Current : 500A Max.
Applicable Cable: 1.25-250sq

Rack·Panel Connector for Bus Bar



PS4


Bus Bar Connector
Rated Current: 300A Max.
(Derating Curve 430A Max.)
±2mm Floating Design

Power In-line



EM12M

1pos. Power Connector
Rated Current: 130A Max.
Applicable Cable: 10.52-42.42sq

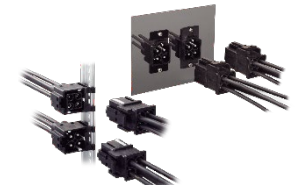

EM35M

Plastic Power Connector
Rated Current: 70A Max.
No. of Pos.: 4
(Three-phase Power+Ground)
Applicable Cable: 5.26-8.92sq