

## 1. Interface Connection (Wire-to-Board)

Noise Resistant

105°C



**GT43**  
Compact,  
One Step Crimping  
Frequency: 3GHz  
Coaxial Cable: 1.5D

Robust

125°C



**ZE05**  
Pitch : 2.0mm  
Rated Current : 2A  
(All pins power supply)  
No. of Pos. : 2-24  
AWG: 20-22

105°C



**GT25**  
Rated Current: 3A  
(All pins Power Supply)  
No. of Pos.: 8-40  
AWG: 20-26

## 2. Internal Connection (Floating Board-to-Board, Wire-to-Board)

Floating Design

125°C



**BM54**  
Compact  
Pitch: 0.4mm  
Stacking Height:  
3.0-4.5mm

125°C



**GT50**  
Rated Current:  
1.5A (6-16pos.)  
2.0A (2,4pos.)  
No. of Pos.: 2-16  
AWG: 28

125°C



**KM32A**  
Rated Current: 5A  
No. of Pos.: 2-10  
AWG: 20


## 2. Internal Connection (Board-to-Board(FPC), Coaxial)

125°C



**DF40T**  
Low Profile,  
Narrow Pitch: 0.4mm  
Stacking Height: 1.5-7.0mm  
1.5 (Shielded Type: DF40GT)

105°C

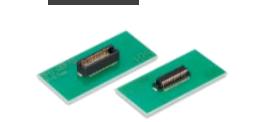

**DF12N**  
Space-saving Design  
Pitch: 0.5mm  
Stacking Height:  
3-5mm

105°C



**POK15**  
Wire-to-Board  
Mated Height:  
14mm  
V.S.W.R.:  
1.5 Max. (0 to 3GHz)

105°C



**POK16**  
Board-to-Board  
Mated Height:  
7.4mm  
V.S.W.R.:  
1.5 Max. (0 to 3GHz)

105°C



**POK19**  
Board-to-Board,  
Wire-to-Board  
Mated Height:9,12mm  
V.S.W.R.:  
1.5 Max. (0 to 6GHz)

105°C



**POK22**  
Floating Design  
Mated Height:16.45mm  
V.S.W.R.:  
1.49 Max. (0 to 6GHz)

## 2. Internal Connection (FPC/FFC, FPC-to-Board)

125°C



**FH75/FH75M** **FH**  
Two-point Contact  
Pitch: 0.5/0.4mm  
Height: 2.0mm  
FH75M: 100pos.

Best Selling




**FH52K** **FH**  
Pitch: 0.5/1.0mm  
Height: 2.0mm

Top/Bottom Contact



**FH79** **FH**  
Pitch: 0.3mm.  
Height: 1.2mm

One Action

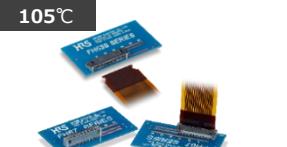

**FH63S/FH67** **FH** **One Action**  
Pitch: 0.5mm  
Height: 2.8, 5.2mm

Top/Bottom Contact



**FH69** **FH**  
Independent  
Two-Point Contact  
Pitch: 0.5mm  
Height: 2.3mm

125°C



**FH65** **FH**  
Low Profile,  
Space-saving Design  
Pitch: 0.5mm  
Height: 1.2mm

Robust



**FH28K** **FH**  
Pitch: 0.5/1.0mm  
Height: 2.55mm

125°C



**ZK1**  
Pitch: 2mm  
Rated Current: 1A  
No. of Pos.: 32