

1. Internal Connection (Floating Board-to-Board)



FX26
Pitch: 1mm
Stacking Height: 15-25mm

FunctionMAX™
140°C
Vibration Absorb
Floating Design



FX23/FX23L
PCIe Gen.4 (16Gbps)
Pitch: 0.5mm
Stacking Height: 8.0-30.0mm

FunctionMAX™
105°C
High Speed
Power / Signal



KP27F
Shielded Type
Pitch: 0.5mm
Stacking Height: 21mm

125°C
Floating Design
Power / Signal



BM54
Compact
Pitch: 0.4mm
Stacking Height: 3.0-4.5mm

2. Internal Connection (FPC/FFC, FPC-to-Board)



FH75/FH75M FH™
Two-point Contact
Pitch: 0.5/0.4mm
Height: 2.0mm
FH75M: 100pos.



FH52K FH™
Pitch: 0.5/1.0mm
Height: 2.0mm



FH63S/FH67 FH™
Pitch: 0.5mm
Height: 2.8, 5.2mm



FH69 FH™
Independent
Two-Point Contact
Pitch: 0.5mm
Height: 2.3mm



FH28K FH™
Pitch: 0.5/1.0mm
Height: 2.55mm



ZK1
Pitch: 2mm
Rated Current: 1A
No. of Pos.: 32




TB4
Pitch: 1mm
Rated Current: 1A
No. of Pos.: 10,16,30

3. Internal Connection (Wire-to-Board)



GT50
Rated Current:
1.5A (6-16pos.)
2.0A (2,4pos.)
No. of Pos.: 2-16
AWG: 28

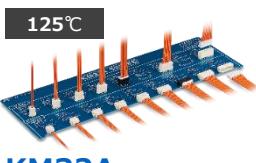

KM32A
Rated Current: 5A
No. of Pos.: 2-10
AWG: 20



ZE05
Rated Current:
2A (All Pins Power Supply)
No. of Pos.: 2-24
AWG: 20-26



ZG05HV
High Voltage 1,000V
Rated Current: 1A
No. of Pos.: 6
AWG: 22-24



GT25
Rated Current: 3A
(All pins Power Supply)
No. of Pos.: 8-40
AWG: 20-26



H VH-280_Internal
Rated Current: 30A
No. of Pos.: 2,3
AWG: 12-14



ZE064W
Rated Current: 30A
No. of Pos.: 2,3
AWG: 12-14



H VH-280 (Waterproof)
IPXXB/IPX9K
Rated Current: 30A
No. of Pos.: 2
AWG: 12-14