

Smart Glasses / スマートグラス


Standard ZIF

Pitch : 0.5mm
Height : 1.0mm



FH34 Series

Pitch : 0.25mm
Height : 0.5mm

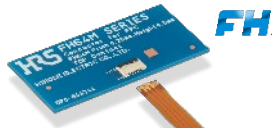

FH64MA Series

Pitch : 0.2/0.25mm
Height : 0.9mm



FH58 Series

One Action Lock

Pitch : 0.3/0.25mm



FH72/FH82 Series

USB Type-C

Top-Mount,
Mid-Mount, Vertical




CX Series


RF Cable and RF Switch

Height : 0.94/1.2mm
Frequency : Up to 12GHz


Height : 0.85mm
Frequency : Up to 11GHz

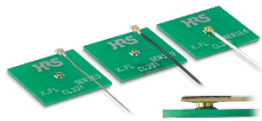

X.FL Series

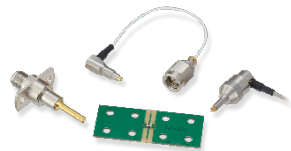

MS-180 Series

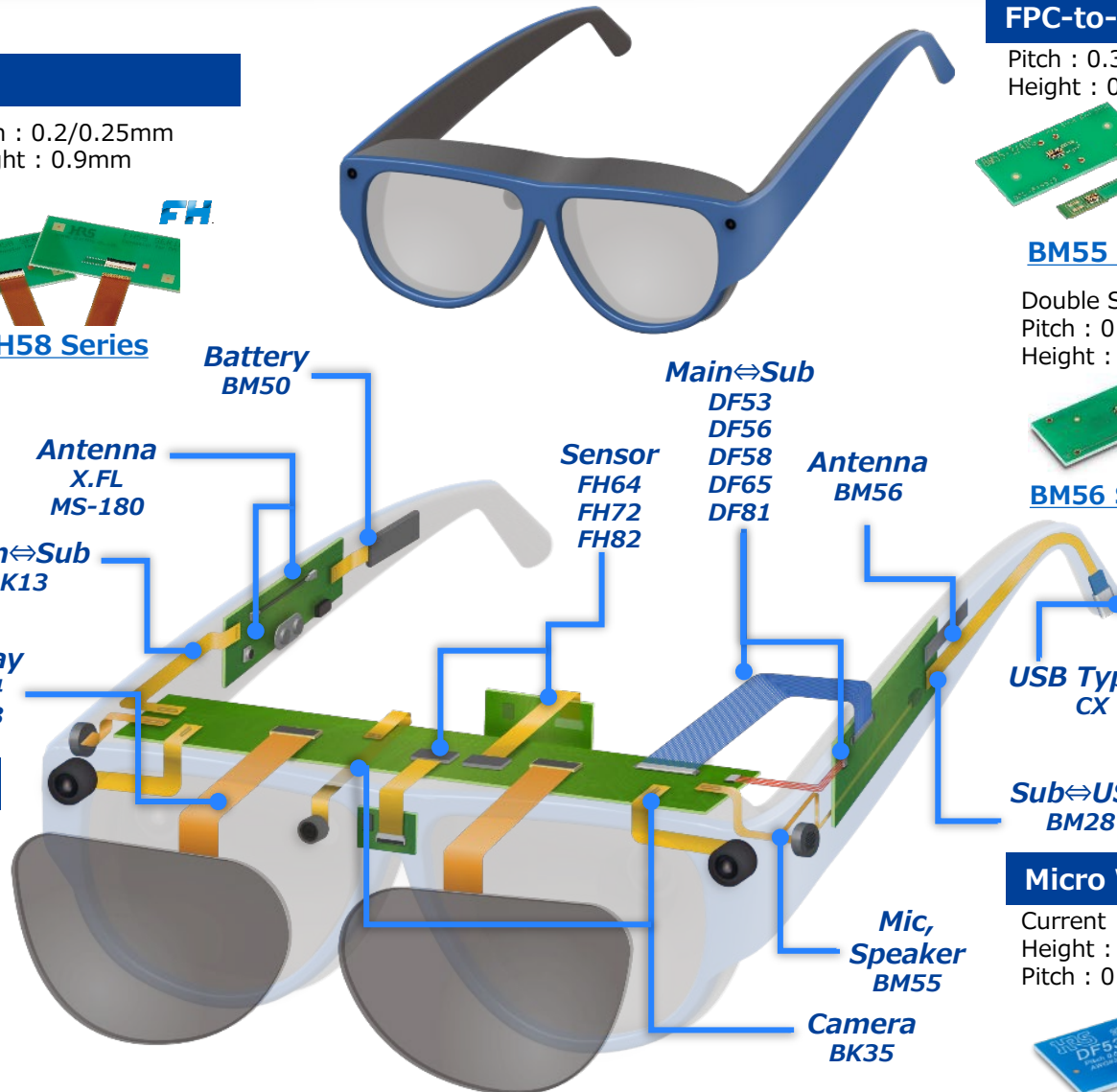


FPC-to-Board

Pitch : 0.3mm
Height : 0.5mm




BM55 Series

 Double Shielded
Pitch : 0.35mm
Height : 0.6mm




BM56 Series

 Height Variation
Pitch : 0.35mm




BK13 Series

Full-Shielded
Pitch : 0.35mm

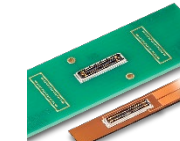


BK35 Series

 Pitch : 0.35mm
Height : 0.6mm



BM28 Series

High Current 15A
Height : 0.6mm

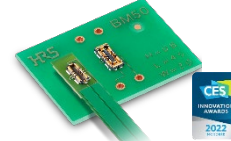

BM50 Series

Coaxial

Pitch : 0.4mm
Depth : 4.4mm



DF81 Series

Pitch : 0.3mm
Depth : 2.6mm



DF56 Series

 
Micro Wire-to-Board

Current : 1.3A Max.
Height : 1.45mm
Pitch : 0.6mm




DF53 Series

Current : 3A Max.
Height : 1.0mm
Pitch : 1.2mm



DF58 Series

 Current : 4.0A Max.
Height : 1.8mm
Pitch : 1.7mm



DF65 Series