



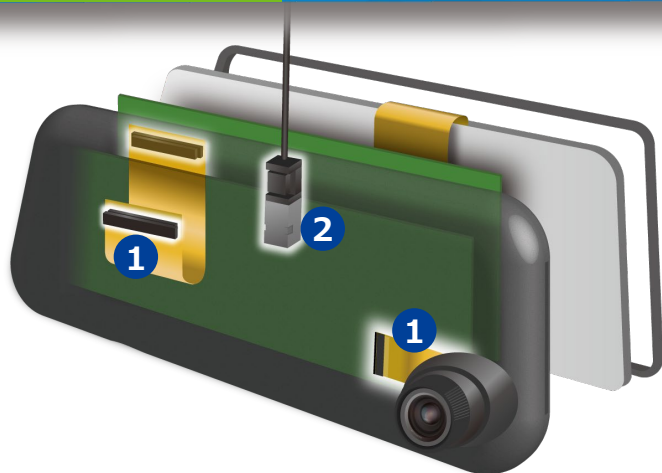

## 1. Internal Connection (FPC/FFC)

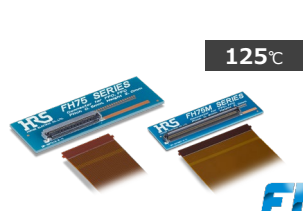

### FH75/FH75M

Pitch : 0.4/0.5mm  
Front Flip  
Two-Point Contact




### FH52K

Pitch : 0.5/1.0mm  
Height : 2.0mm



### FH63S

Horizontal Connection  
Pitch : 0.5mm  
Height : 2.8mm

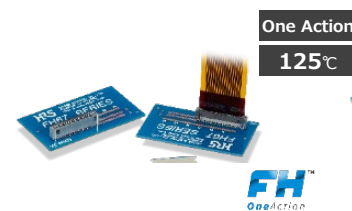

### FH67

Vertical Connection  
Pitch : 0.5mm  
Height : 5.2mm



### FH69


Back Flip  
Independent  
Two-Point Contact  
Pitch : 0.5mm  
Height : 2.3mm

## 1. Internal Connection (FPC/FFC)




### FH65

Low Profile,  
Space-saving Design  
Pitch : 0.5mm  
Height : 1.2mm

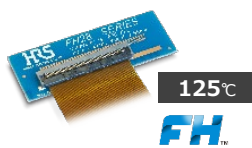


### FH28K

Pitch : 0.5/1.0mm  
Height : 2.55mm

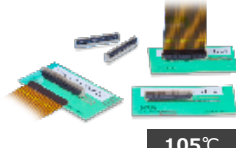

### FH40

Vertical Connection  
Pitch : 0.5mm  
Height : 5.8mm

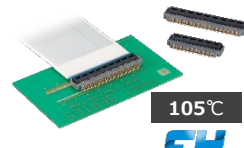


### FH41

Shielded FFC  
Pitch : 0.5mm  
Height : 2.5mm



### FH48

Vertical Connection  
Shielded FFC  
Pitch : 0.5mm  
Height : 6.18mm

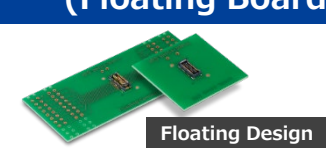


### BM54

Floating, Compact  
Pitch : 0.4mm  
Stacking Height : 3.0-4.5mm



### DF40T

Low Profile,  
Narrow Pitch : 0.4mm  
Stacking Height : 1.5-7.0mm  
1.5 (Shielded Type : DF40GT)

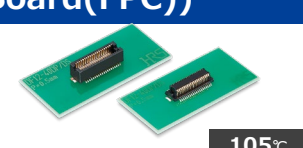

### DF12N


Space-saving Design  
Pitch : 0.5mm  
Stacking Height : 3-5mm

## 1. Internal Connection (Coaxial, Wire-to-Board)



### POK15

Wire-to-Board  
Mated Height : 14mm  
V.S.W.R. :  
1.5 Max. (0 to 3GHz)

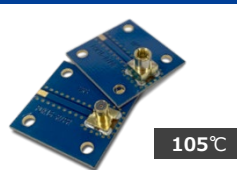


### POK16

Board-to-Board  
Mated Height : 7.4mm  
V.S.W.R. :  
1.5 Max. (0 to 3GHz)



### POK19


Board-to-Board,  
Wire-to-Board  
Mating Height : 9, 12mm  
V.S.W.R. :  
1.5 Max. (0 to 6GHz)

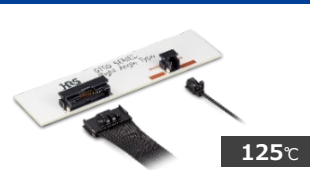

### GT50


Pitch : 1.0mm  
Rated Current :  
1.5A (6-16pos.) / 2.0A (2, 4pos.)  
No. of Pos. : 2, 4, 6, 8, 12, 16  
AWG : 28

## 2. Interface Connection (High Speed Wire-to-Board, Wire-to-Board)

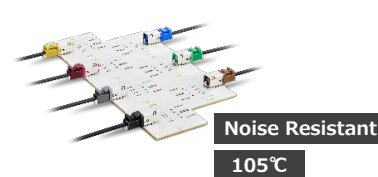


### GT43

Compact  
One Step Crimping  
Frequency : 3GHz  
Coaxial cable : 1.5D

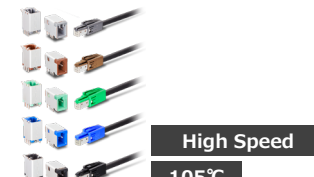

### GT32

Transmission Rate :  
4pos. : 1Gbps Max./pair (USB2.0, LVDS Equivalent)  
10pos. : 5Gbps Max./pair (USB3.2 Gen.1 Equivalent)  
19pos. : 2.2Gbps Max./pair (HDMI 1.4a Type E Equivalent)  
AWG : 24-28AWG  
Cable Type : Twist

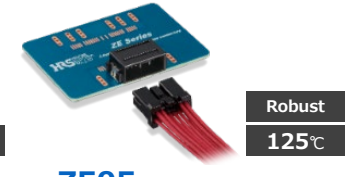

### ZE05

Pitch : 2mm  
Rated Current :  
2A (All pins power supply)  
No. of Pos. : 2-24  
AWG : 20-22