

Handy Terminal POS

Display, Sub to Main, Key Pad

Standard ZIF
Pitch : 0.5mm



[FH34 Series](#)

One Action Lock
Pitch: 0.25mm/0.3mm

OneAction FH™



[FH62/FH72 Series](#)


Low Profile ZIF,
Height : 0.5mm

FH




[FH64 Series](#)

Narrow Hybrid,
Depth : 1.7mm

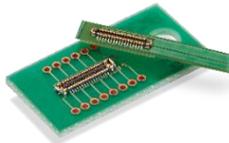

[BM28 Series](#)

Narrow Hybrid,
Depth : 1.9mm

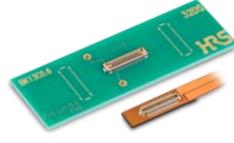

[BK13 Series](#)

Interface (In Socket Device)

Compact,
Vertical, Mid-Mount, Top-Mount



[CX Series](#)

Battery

High Current
10A



[BM25 Series](#)


FPC-to-Board

High Current
15A



[BM50 Series](#)

High Current
15A

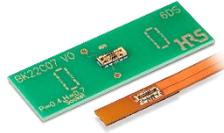

[BK22 Series](#)

Antenna

Standard RF



[U.FL Series](#)

RF Switch



[MS-156C Series](#)

Scan Camera Board

Wide Variation
Height : 1.5-7.0mm



[DF40 Series](#)

Wide Variation
Height : 3.0-5.0mm



[DF12N Series](#)

Wide Variation
Height : 4.0-8.0mm



[DF17 Series](#)

Small floating
Height : 3.0-4.5mm



[BM54 Series](#)