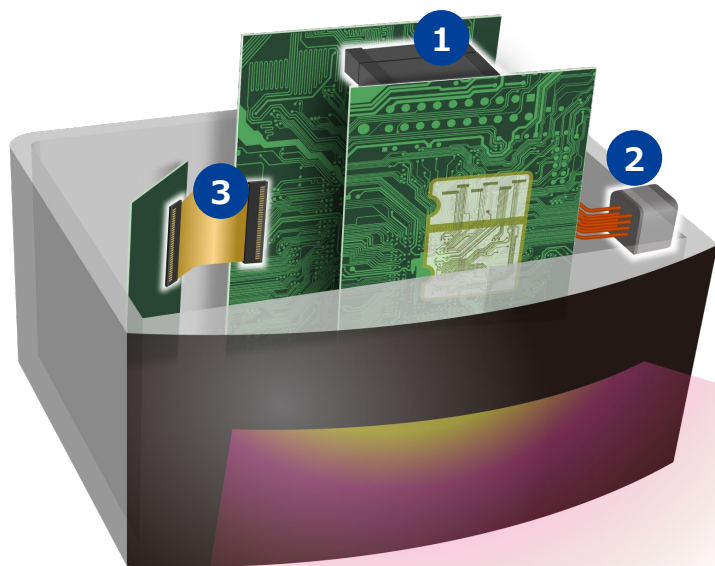
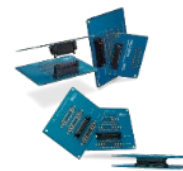


 


1. Internal Connection (Floating Board-to-Board, Board-to-Board(FPC))


FunctionMAX™
105℃
High Speed
Power / Signal

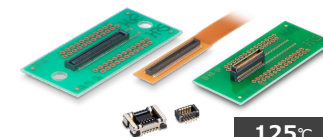
FX23/FX23L

PCIe Gen.4 (16Gbps)
Pitch : 0.5mm
Stacking Height : 8-30mm


Floating Design
125℃

BM54

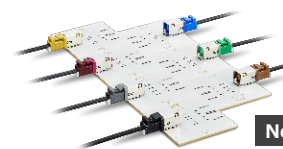
Floating, Compact
Pitch : 0.4mm
Stacking Height : 3.0-4.5mm


125℃

DF40T

Low Profile,
Narrow Pitch : 0.4mm
Stacking Height : 1.5-7.0mm
1.5 (Shielded Type : DF40GT)

2. Interface Connection (High Speed Wire-to-Board, Wire-to-Board)


Noise Resistant
105℃

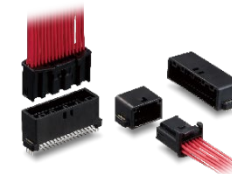
GT43

Compact, One Step Crimping
Frequency : 3GHz
Coaxial Cable : 1.5D


Robust
125℃

ZE05

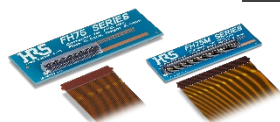
Pitch : 2mm
Rated Current :
2A (All pins power supply)
No. of Pos. : 2-24
AWG : 20-22


105℃

GT25

Pitch : 2.2mm
Rated Current :
3A (All pins power supply)
No. of Pos. : 8-40
AWG : 20-26

3. Internal Connection (FPC/FFC, Wire-to-Board)


125℃
Best Selling
125℃

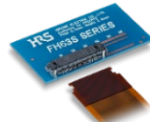
FH75/FH75M

Pitch : 0.4/0.5mm
Front Flip
Two-Point Contact

FH™


FH52K

Pitch : 0.5/1.0mm
Height : 2.0mm

FH™

One Action
125℃

FH63S

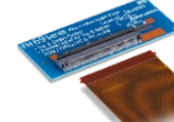
Horizontal Connection
Pitch : 0.5mm
Height : 2.8mm

FH™

One Action
125℃

FH67

Vertical Connection
Pitch : 0.5mm
Height : 5.2mm

FH™

125℃

FH69

Back Flip
Independent
Two-Point Contact
Pitch : 0.5mm
Height : 2.3mm

FH™

125℃

FH65

Low Profile,
Space-saving Design
Pitch : 0.5mm
Height : 1.2mm

FH™

125℃

GT50

Pitch : 1.0mm
Rated Current :
1.5A (6-16pos.)
/2.0A (2, 4pos.)
No. of Pos. : 2, 4, 6, 8, 12, 16
AWG : 28