


# Smart Thermostat

Click here to request a sample

## Touch Panel Sensor

Low Profile ZIF,  
Height: 0.5mm

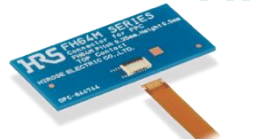

FH64 Series


One Action Lock  
间距: 0.25/0.3mm  
**OneAction FH™**



FH62/FH72 Series

## Display

Standard ZIF  
Pitch: 0.3mm

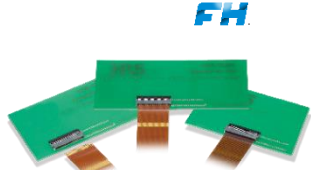

FH35C Series


One Action Lock  
Pitch: 0.25mm  
**OneAction FH™**



FH62 Series

## Speaker

Snap Lock, 3A Max.  
Height: 1.0mm

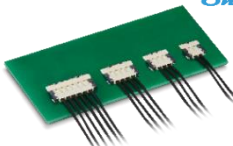

DF58 Series

Snap Lock, 4A Max.  
Height: 2.0mm



DF61Y Series

## Antenna

Frequency:  
Up to 18GHz



U.FL(A) Series

RF Switch  
Frequency: 0 to 11GHz



MS-180 Series

## Interface


6A Max.  
IPX8 Waterproof



CX Series

## Buttons/Any Connections

Narrow Hybrid, 5A  
Depth: 1.7mm

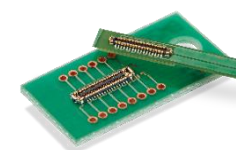

BM28 Series

Wide Variation  
Height: 1.5-7.0mm



DF40 Series

Standard ZIF  
Pitch: 0.5mm, Height 1.0mm



FH34 Series

Standard ZIF  
Pitch: 0.5/1.0mm



TF31 Series