



HRS Integrated Solution for Delivery Robot/AGV/AMR

Interconnect Solutions for Delivery Robot: LiDAR, Camera, Sensor, Wireless and FAN Module Connections

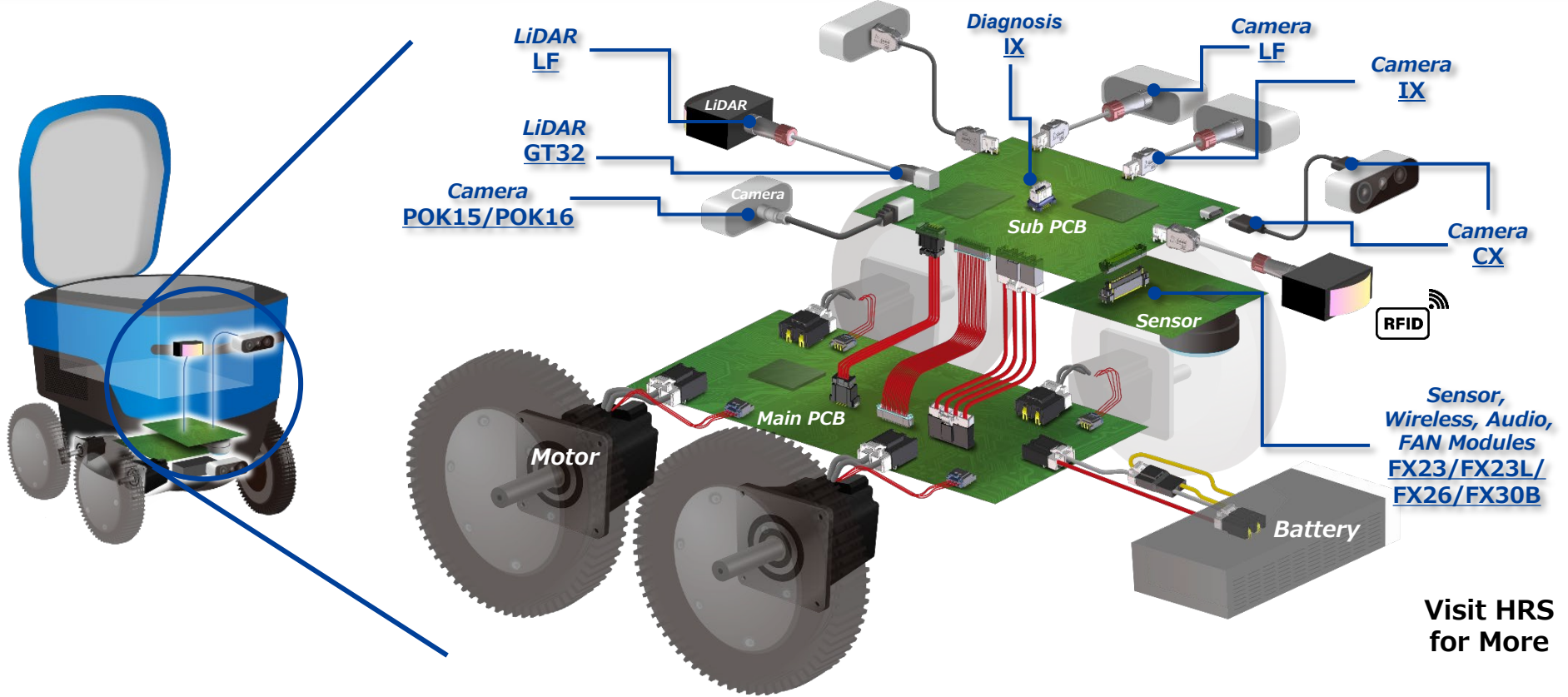

Visit HRS for More

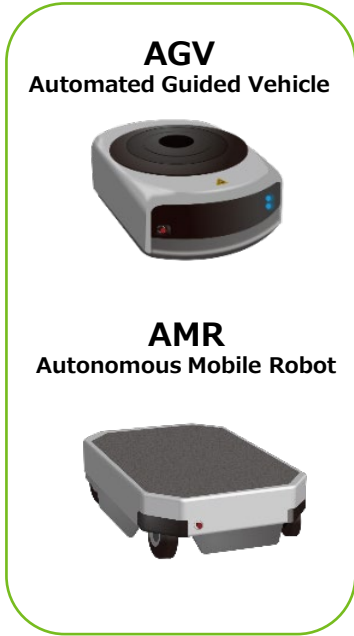

LiDAR & Camera



IX
Compact and Robust Cat.6A I/O




CX
USB Type-C Connector Supporting Up to 20Gbps

Automotive Grade



GT32
1Gbps, Space-saving Shielded Signal I/O

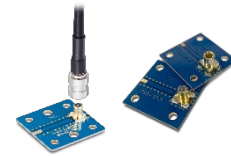

POK15/POK16
3GHz, Coaxial Wire-to-Board & Board-to-Board



LF
Shielded Waterproof I/O


Sensor, Wireless, and FAN Modules

Automotive Grade



FX23/FX23L
High Speed Floating Board-to-Board with Power Contacts

Automotive Grade


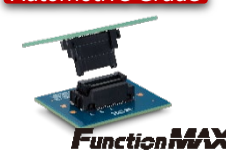


FX26
Vibration Absorbing, Floating Board-to-Board



FX30B
Board-to-Board Power Connectors With Misalignment Absorption

Interconnect Solutions for Delivery Robot: Motor Signal, PCB, Motor Power and Battery Connections

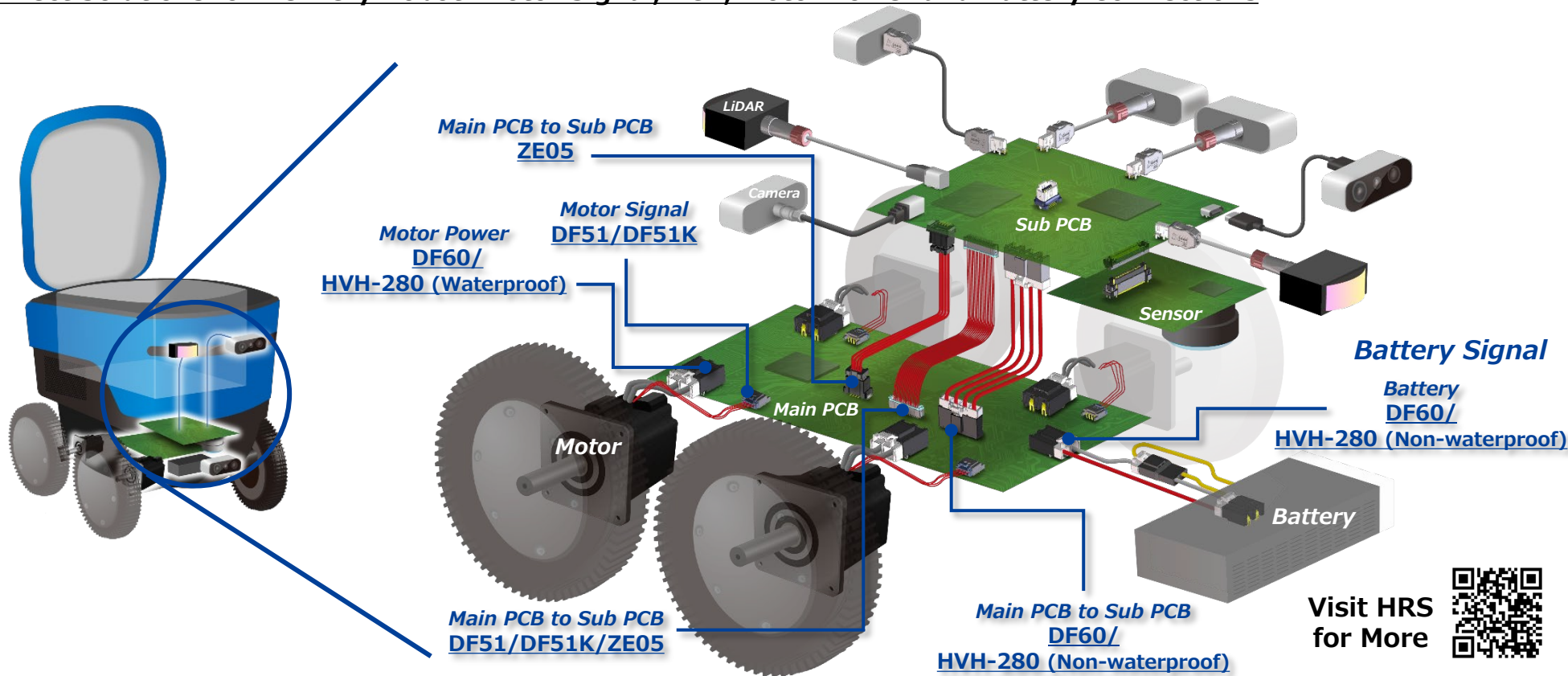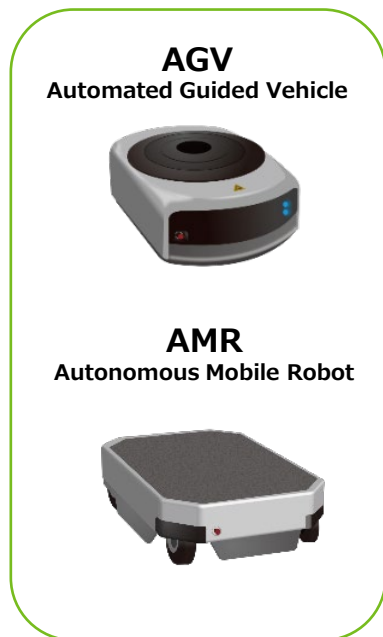


Motor Signal & PCB

Automotive Grade



ZE05

125°C Heat Resistant,
High Vibration Resistance

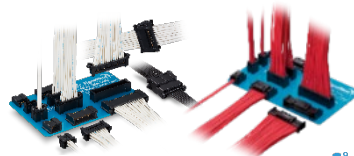

DF51/DF51K

2.0mm Pitch,
Positive Lock
Wire-to-Board



Motor Power & Battery

Automotive Grade



DF60

65A Max.*Current,
Positive Lock
Wire-to-Board

*UL Standard



HVH-280 (Non-waterproof)

125°C Heat Resistance
30A Wire-to-Board



HVH-280 (Waterproof)

30A Waterproof Panel
Mount I/O

Automotive Grade