

Smart Glasses

Standard ZIF

Pitch : 0.5mm
Height : 1.0mm



FH34 Series

Pitch : 0.25mm
Height : 0.5mm



FH64 Series

Pitch : 0.2/0.25mm
Height : 0.9mm



FH58 Series

One Action Lock

Pitch : 0.3/0.25mm



FH72/FH82 Series

USB Type-C

Top-Mount,
Mid-Mount, Vertical



CX Series

RF Cable and RF Switch

Height : 0.94/1.2mm
Frequency : Up to 12GHz




X.FL Series

Height : 0.85mm
Frequency : Up to 11GHz



MS-180 Series

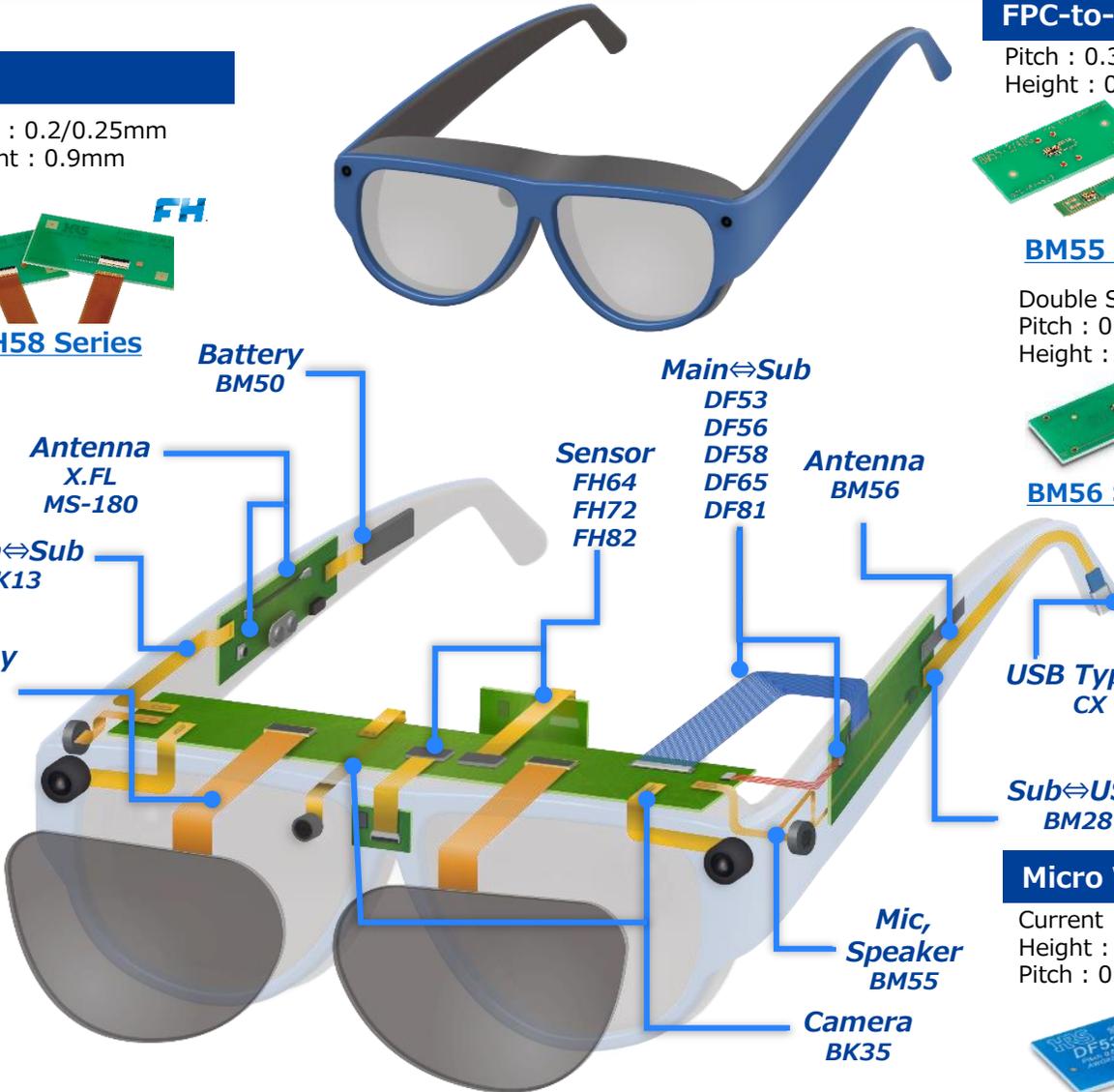

FPC-to-Board

Pitch : 0.3mm
Height : 0.5mm



BM55 Series

Double Shielded
Pitch : 0.35mm
Height : 0.6mm



BM56 Series

Height Variation
Pitch : 0.35mm



BK13 Series

Full-Shielded
Pitch : 0.35mm



BK35 Series

Pitch : 0.35mm
Height : 0.6mm



BM28 Series

High Current 15A
Height : 0.6mm



BM50 Series

Coaxial

Pitch : 0.4mm
Depth : 2.75mm



DF81 Series

Pitch : 0.3mm
Depth : 2.6mm



DF56 Series

Micro Wire-to-Board

Current : 1.3A Max.
Height : 1.45mm
Pitch : 0.6mm



DF53 Series

Current : 3A Max.
Height : 1.0mm
Pitch : 1.2mm



DF58 Series

Current : 4.0A Max.
Height : 1.8mm
Pitch : 1.7mm



DF65 Series

*The CES Innovation Awards are based upon descriptive materials submitted to the judges. CTA did not verify the accuracy of any submission or of any claims made and did not test the item to which the award was given.