


Smart Dog Collar

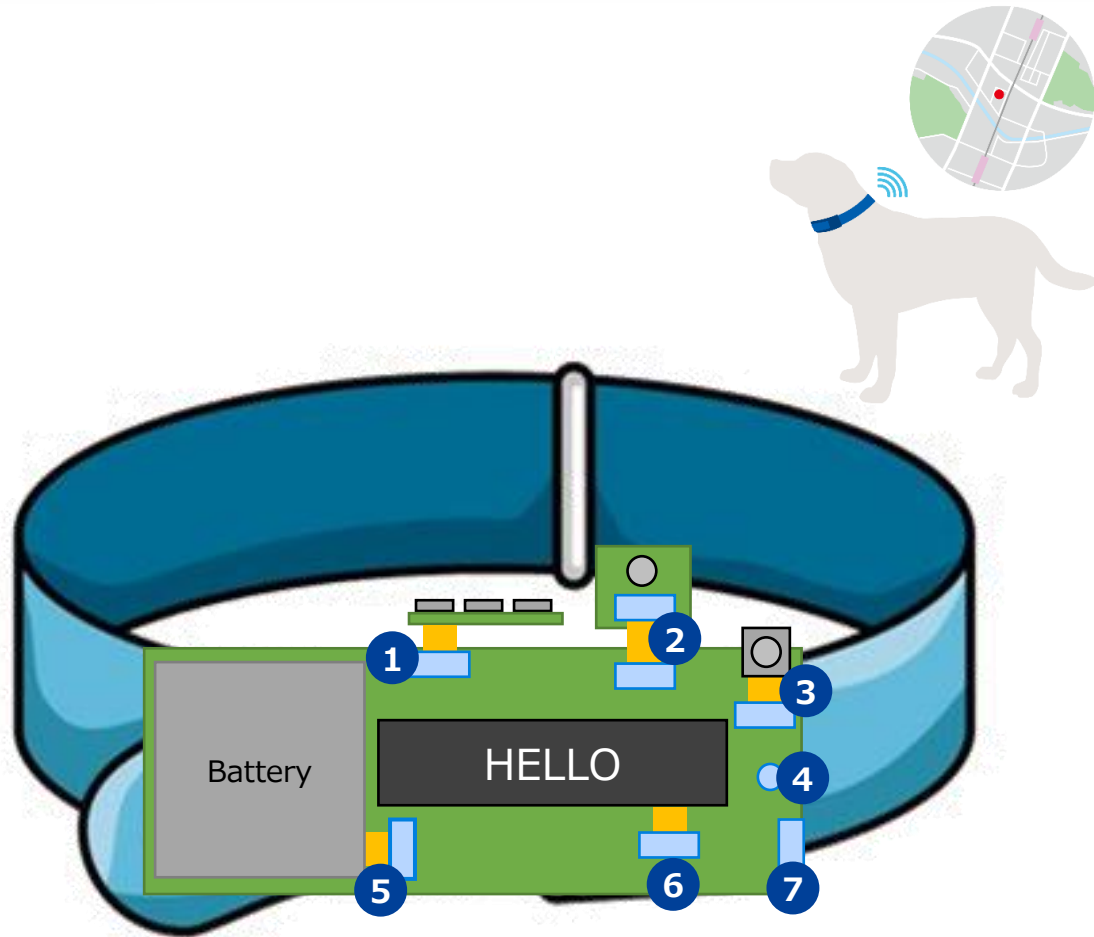


1. Buttons / 2. Speaker, Sensors / 3. Camera / 4. Display

Standard ZIF
Pitch: 0.5mm



[FH34 Series](#)

Narrow Hybrid, 5A
Depth: 1.7mm

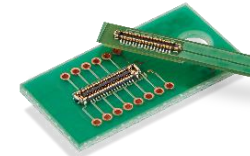


[BM28 Series](#)

Snap Lock,
3A Max.



[DF57 Series](#)

2-4,6pos.,
3A Max.

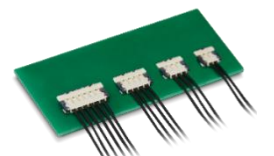


[DF58 Series](#)

1. Buttons

One Action
Pitch: 0.25/0.3mm

OneAction **FH**

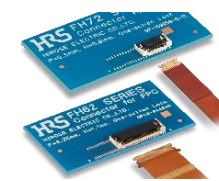


[FH62/FH72 Series](#)

2. Speaker & Sensors

Low Profile ZIF,
Height: 0.5mm

FH

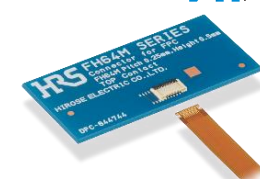

[FH64 Series](#)

4. Antenna Switch


RF Switch



[MS-180 Series](#)

5. Battery

Narrow Battery,
Depth: 1.5mm

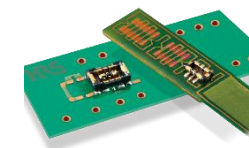

[BM29 Series](#)

6. Interface

USB Type-C,
6A Max.



[CX Series](#)